



Custom-Made 19" 2URack Power System

- Standard 19" 2U rack – 480 x 420 x 80mm
- Custom rack configurations available, 4500W max., up to 8 outputs
- LED indicators on front panel
- Meters for output voltage and current on front panel
- Front panel voltage adjustment
- Wide range of backplane connection option
- Choose from MEAN WELL's wide range of standard power supply
- Complete assembly and testing on your custom rack system
- Engineering support available to assist you in specifying your requirement
- 2 years warranty

Panel Type A: with power switch, LED indicators, and output adjustment potentiometers.

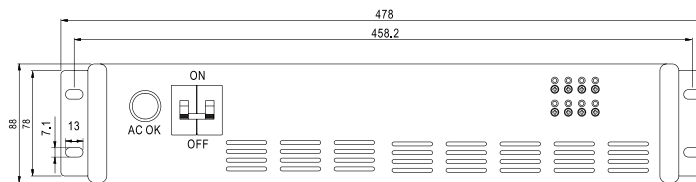

Panel Type B: with additional digital meters and selector switch.

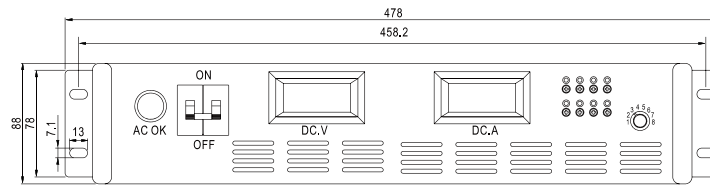

Example

❖ 12V, 4500W 2U Rack System

- RSP-1500-12 x 3pcs
- LED indicators and front panel voltage adjustment
- Output voltage and current digital meters
- I/O interface:
 - AC Input — Terminal block
 - DC Output — Copper pillars
 - Single Output — Terminal block