

## Specification

### LED Linear Light (J Series)



#### NOTES:

1. This specification for custom manufacturing product specifications.
2. The right of final interpretation of this specification to Guangzhou LEDIA Lighting Co., Ltd




### 1. Descriptions

- ◆ LED Linear Light
- ◆ Ideal replacement of fluorescent fixtures
- ◆ Perfect to apply in: supermarket, factory, ware house, workshop, parking lots, etc

### 2. Characteristics

- ◆ Seamless Connection.
- ◆ Surface Mount and Pendant Mount Options.
- ◆ Light Weight With One Piece Plastic Housing.
- ◆ Use Hongli 2835SMD LEDs, with stable performance, high efficacy.

### 3. Applications

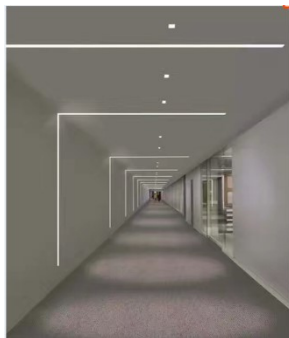

## 4. Technical Parameters



Code	LD-LF-J030-****
Power ( W )	30W
LED Driver	/
PF	/
Input Voltage (V)	DC 360~400V( with MEANWELL driver)
Efficacy (lm/W)	120
Maintenance (L70)	36001m
CCT ( K )	4000K
Dimming	No
CRI	>80
Beam angle	120°
Material	Aluminum+ PC
Operating Temperature	-20℃ to 40℃
Humidity	10% - 90%,
Installation	Suspended/Surface mounted
Connection	N/A
Certification	CE CCC
Environment	Indoor/outdoor
Warranty	5 Years
Product size (mm)	1200*66.5*58mm

### Notes

1. \*\*stands for 3000K、3500K、4000K、5000K、6000、6500K
2. Efficacy is 10% lower for CCT below 4000K

## 5. Photometric Data

LUMINOUS INTENSITY DISTRIBUTION DIAGRAM

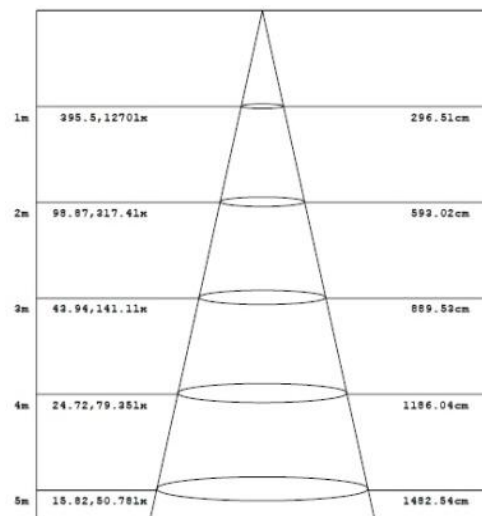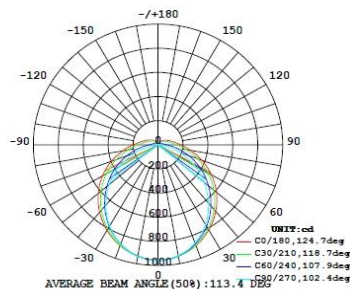

NOTE: For more photometric information, please contact our sales staff